
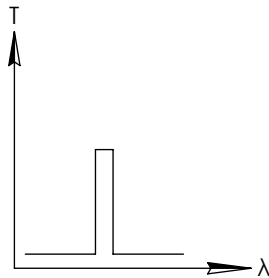
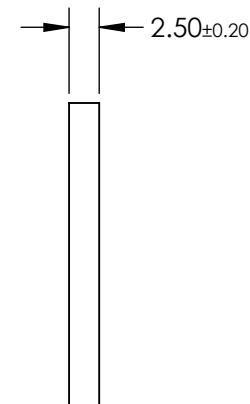
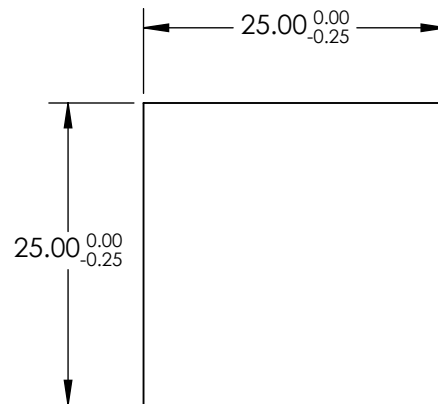


**FOR INFORMATION ONLY:
DO NOT MANUFACTURE
PARTS TO THIS DRAWING**

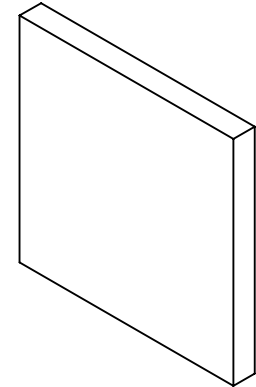

BANDPASS FILTER

SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE
DIMENSIONS ARE FOR REFERENCE ONLY

	VALUE
SHAPE	PLANO
CENTER WAVELENGTH (nm)	330
FULL WIDTH HALF MAX (FWHM) (nm)	140
SURFACE QUALITY	60-40
CAOTING TYPE	Uncoated
BEVEL	PROTECTIVE AS NEEDED



ALL DIMS IN mm

TITLE	U-330 (UV) 25mm Square, Colored Glass Bandpass Filter
DWG NO	46083
SHEET 1 OF 1	