
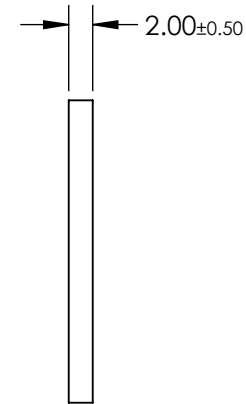
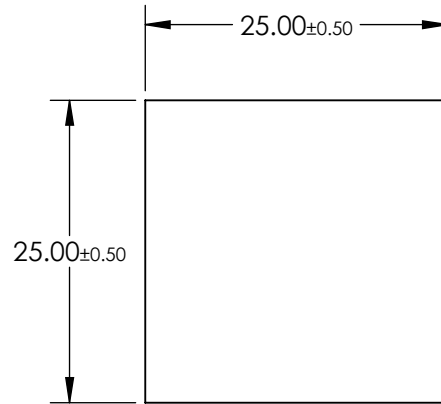


**FOR INFORMATION ONLY:
DO NOT MANUFACTURE
PARTS TO THIS DRAWING**

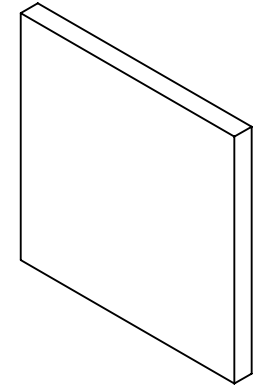

SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE
DIMENSIONS ARE FOR REFERENCE ONLY

SUBSTRATE	Fused Silica
GROOVE DENSITY (grooves/mm)	830
WAVELENGTH RANGE (nm)	250 - 450
BLAZE ANGLE	19.4°
RoHS	COMPLIANT

EO[®] Edmund Optics[®]



ALL DIMS IN mm

TITLE

830 Grooves/mm, 25mm Sq, UV Transmission
Grating Beamsplitter

DWG NO

85294

SHEET
1 OF 1