
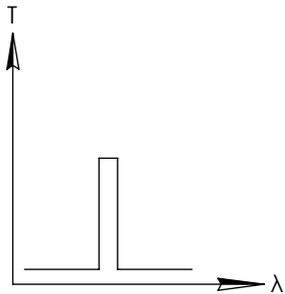
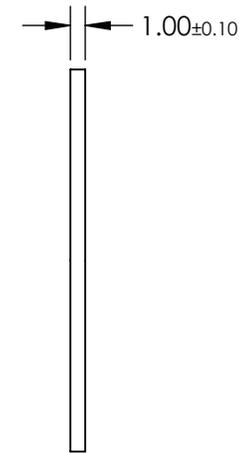
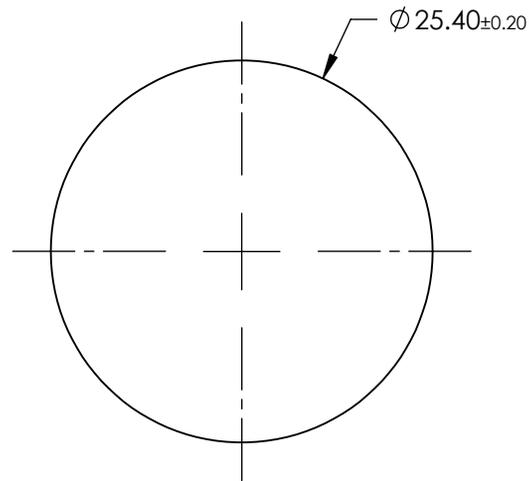


NOTES:

- SUBSTRATE: COLORED GLASS

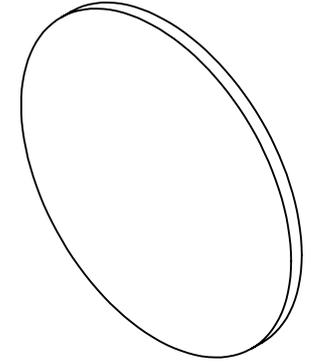


BANDPASS FILTER

**FOR INFORMATION ONLY:
DO NOT MANUFACTURE
PARTS TO THIS DRAWING**

SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE
DIMENSIONS ARE FOR REFERENCE ONLY

	VALUE
SHAPE	PLANO
CENTER WAVELENGTH (nm)	340.00
FULL WIDTH HALF MAX (FWHM) (nm)	85.00
SURFACE QUALITY	60-40
COATING TYPE	UNCOATED
BEVEL	PROTECTIVE AS NEEDED

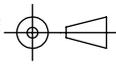THIRD ANGLE PROJECTION 

ALL DIMS IN mm

 **Edmund Optics®**

TITLE	Hoya U340 (UV) 25.4mm Dia., 1mm Thick, Colored Glass Bandpass Filter
DWG NO	18767
	SHEET 1 OF 1