



NOTES:

1. SUBSTRATE: COLORED GLASS

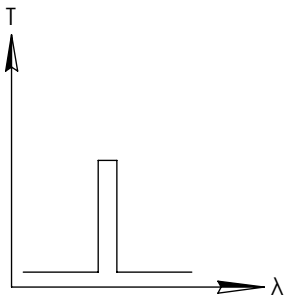

BANDPASS FILTER

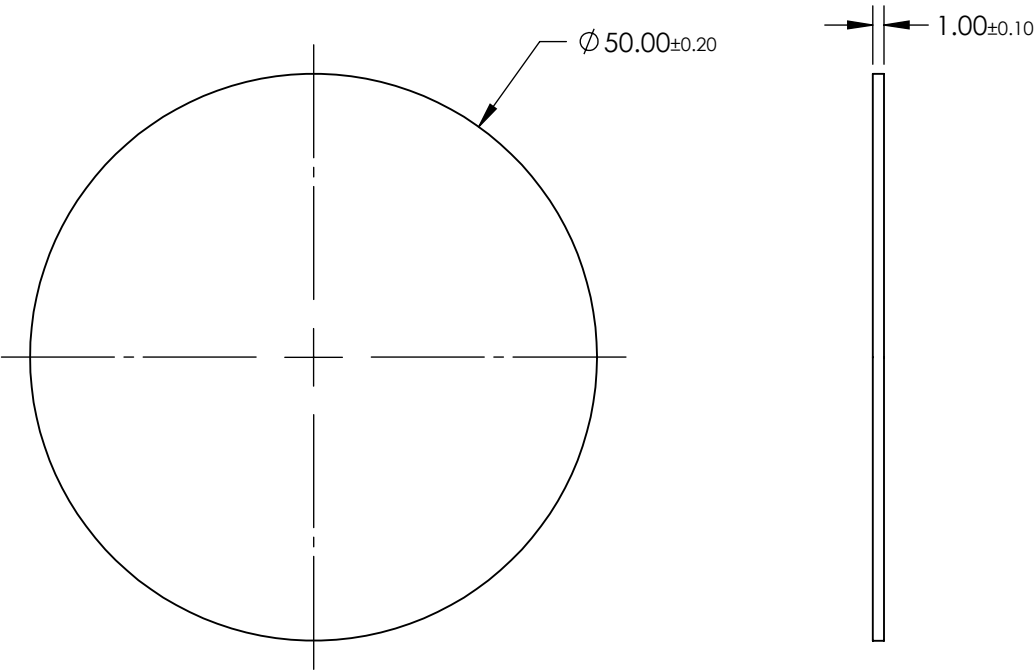

**FOR INFORMATION ONLY:  
DO NOT MANUFACTURE  
PARTS TO THIS DRAWING**


SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE  
DIMENSIONS ARE FOR REFERENCE ONLY

|                                 | VALUE                |
|---------------------------------|----------------------|
| SHAPE                           | PLANO                |
| CENTER WAVELENGTH (nm)          | 390.00               |
| FULL WIDTH HALF MAX (FWHM) (nm) | 125.00               |
| SURFACE QUALITY                 | 60-40                |
| COATING TYPE                    | UNCOATED             |
| BEVEL                           | PROTECTIVE AS NEEDED |

THIRD ANGLE  
PROJECTION

ALL DIMS IN

mm

 **Edmund Optics®**

|        |  |                 |  |
|--------|--|-----------------|--|
| TITLE  | Hoya B390 (UVVIS) 50mm Dia., 1mm Thick,<br>Colored Glass Bandpass Filter |                 |  |
| DWG NO | 18783  | SHEET<br>1 OF 1 |  |