

[Alle Produkte](#) / [Optikkomponenten](#) / [Strahlteiler](#) / [Strahlteilerwürfel](#)

TECHSPEC® Strahlteilerwürfel in C-Mount-Halterung



- Vereinfachte Montage und Ausrichtung
- Löcher mit standardmäßigem C-Mount-Innengewinde
- Standardstrahlteiler und Strahlteiler ohne Polarisierung
- Zusätzliche [Strahlteiler](#), [Filter](#) und [Spiegel](#) mit C-Mount erhältlich

Spezifikationen

Physikalische und mechanische Eigenschaften

Aufbau:	Cube	Größe (mm):	38.0 x 38.0 x 50.0
Tubuslänge (mm):	38.0	Gehäuse:	Black Anodized Aluminum


Optische Eigenschaften

Verhältnis Reflexion/Transmission (R/T):	50/50	Toleranz Reflexion/Transmission (%):	±5
Substrat:	N-BK7	Passfehler, Power (Ringe) @ 632,8 nm:	1.25
Unregelmäßigkeit (Ringe) @ 632,8 nm:	0.25		

Gewinde & Montage

Mount:	C-Mount Enclosure
Gewindeart:	C-Mount (1" x 32 TPI)

Technische Informationen

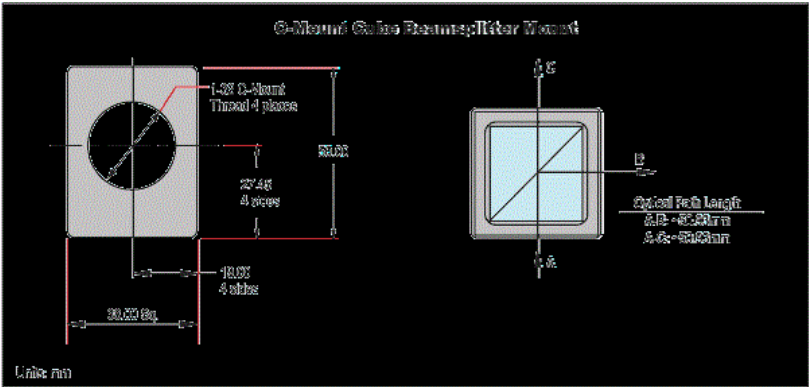

Produkte

Größe (mm)	Wellenlängenbereich (nm)	Verhältnis Reflexion/Transmission (R/T)	Optiktyp	Artikelnummer	Preis	Kaufen
38.0 x 38.0 x 50.0	400 - 700	50/50	Standard Cube Beamsplitter	#54-823	€344,02 Mengenrabatte	8 In Stock
38.0 x 38.0 x 50.0	430 - 670	50/50	Non- Polarizing Cube Beamsplitter, VIS Coating	#49-682	€428,48 Mengenrabatte	3 In Stock
38.0 x 38.0 x 50.0	720 - 1080	50/50	Non- Polarizing Cube Beamsplitter, NIR Coating	#49-683	€448,05 Mengenrabatte	2 In Stock



Copyright 2023 | Edmund Optics, Ltd Unit 1, Opus Avenue, Nether Poppleton, York, YO26 6BL, UK
Telefonnr.: 1-800-363-1992 :
www.edmundoptics.com