


[Alle Produkte](#) / [Optikkomponenten](#) / [Polarisationsoptiken](#) / [Lineare Polarisationsfilter](#) / [Absorbierende \(dichroitische\) Polarisationsfilter](#) / [Polymer-Polarisationsfolien](#)

TECHSPEC®

Lineare Polarisationsfilme für hohe Temperaturen (XP40HT)

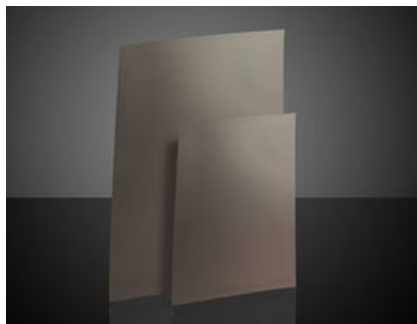

- Hohe Temperaturresistenz verglichen mit üblichen Polarisationsfilmen
- Auslöschungsverhältnis von 5000:1
- Hohe Transmission von unpolarisiertem Licht zwischen 400 und 700 nm
- Kundenspezifische Größen verfügbar

Spezifikationen

Physikalische und mechanische Eigenschaften

Aufbau: Polarizing Film

Optische Eigenschaften

Auslöschungsverhältnis: 5000:1

Wellenlängenbereich (nm):	400 - 700	Polarisationseffizienz (%):	>99.5
Transmission, Parallel (%):	32.2	Transmission, gekreuzt (%):	<0.005

Umwelt & Haltbarkeit

Hitzeresistenz (°C x Stunden):	100 x 1,000	Kälteresistenz (°C x Stunden):	-40 x 1,000
Feuchtigkeitsresistenz (°C x Stunden):	80 x 90% RH x 1,000		

Technische Informationen

Produkte

Durchm. (mm)	Größe (mm)	Dicke (mm)	Beschichtung	Substrat	Artikelnummer	Preis	Kaufen
10.00	-	0.19	Uncoated, Protective Film Both Sides	Polymer Film XP40HT- 18	#73-133	€18,54 Mengenrabatte	20+ In Stock
10.00	-	0.40	Uncoated, Protective Film Both Sides	Polymer Film XP40HT- 40	#73-141	€18,54 Mengenrabatte	20+ In Stock
12.50	-	0.19	Uncoated, Protective Film on Both Sides	Polymer Film XP40HT- 18	#29-465	€19,57 Mengenrabatte	20+ In Stock
12.50	-	0.40	Uncoated, Protective Film on Both Sides	Polymer Film XP40HT- 40	#29-476	€19,57 Mengenrabatte	20+ In Stock
15.00	-	0.19	Uncoated, Protective Film Both Sides	Polymer Film XP40HT- 18	#73-136	€20,60 Mengenrabatte	20+ In Stock
15.00	-	0.40	Uncoated, Protective Film Both Sides	Polymer Film XP40HT- 40	#73-142	€20,60 Mengenrabatte	20+ In Stock
20.00	-	0.19	Uncoated, Protective Film Both Sides	Polymer Film XP40HT- 18	#73-137	€21,63 Mengenrabatte	20+ In Stock
20.00	-	0.40	Uncoated, Protective Film Both Sides	Polymer Film XP40HT- 40	#73-148	€21,63 Mengenrabatte	20+ In Stock
25.00	-	0.19	Uncoated, Protective Film on Both Sides	Polymer Film XP40HT- 18	#29-466	€22,66 Mengenrabatte	20+ In Stock
25.00	-	0.40	Uncoated, Protective Film on Both Sides	Polymer Film XP40HT- 40	#29-477	€22,66 Mengenrabatte	20+ In Stock

-	25.0 x 25.0	0.19	Uncoated, Protective Film on Both Sides	Polymer Film XP40HT- 18	#29-456	€22,66 Mengenrabatte	10 In Stock
-	25.0 x 25.0	0.40	Uncoated, Protective Film on Both Sides	Polymer Film XP40HT- 40	#29-468	€22,66 Mengenrabatte	16 In Stock
30.00	-	0.19	Uncoated, Protective Film Both Sides	Polymer Film XP40HT- 18	#73-138	€24,72 Mengenrabatte	20+ In Stock
30.00	-	0.40	Uncoated, Protective Film Both Sides	Polymer Film XP40HT- 40	#73-149	€24,72 Mengenrabatte	20+ In Stock
40.00	-	0.19	Uncoated, Protective Film Both Sides	Polymer Film XP40HT- 18	#73-140	€28,84 Mengenrabatte	20+ In Stock
40.00	-	0.40	Uncoated, Protective Film Both Sides	Polymer Film XP40HT- 40	#73-150	€28,84 Mengenrabatte	20+ In Stock
50.00	-	0.19	Uncoated, Protective Film on Both Sides	Polymer Film XP40HT- 18	#29-467	€30,90 Mengenrabatte	20+ In Stock
50.00	-	0.40	Uncoated, Protective Film on Both Sides	Polymer Film XP40HT- 40	#29-478	€30,90 Mengenrabatte	20+ In Stock
-	50.0 x 50.0	0.19	Uncoated, Protective Film on Both Sides	Polymer Film XP40HT- 18	#29-457	€30,90 Mengenrabatte	15 In Stock
-	50.0 x 50.0	0.40	Uncoated, Protective Film on Both Sides	Polymer Film XP40HT- 40	#29-469	€30,90 Mengenrabatte	8 In Stock
-	100.0 x 100.0	0.19	Uncoated, Protective Film on Both Sides	Polymer Film XP40HT- 18	#29-458	€53,56 Mengenrabatte	6 In Stock
-	100.0 x 100.0	0.40	Uncoated, Protective Film on Both Sides	Polymer Film XP40HT- 40	#29-470	€53,56 Mengenrabatte	20+ In Stock

-	150.0 x 150.0	0.19	Uncoated, Protective Film on Both Sides	Polymer Film XP40HT- 18	#29-459	€72,10 Mengenrabatte	20+ In Stock
-	150.0 x 150.0	0.40	Uncoated, Protective Film on Both Sides	Polymer Film XP40HT- 40	#29-471	€72,10 Mengenrabatte	6 In Stock
-	200.0 x 200.0	0.19	Uncoated, Protective Film on Both Sides	Polymer Film XP40HT- 18	#29-460	€123,60 Mengenrabatte	20+ In Stock
-	200.0 x 200.0	0.40	Uncoated, Protective Film on Both Sides	Polymer Film XP40HT- 40	#29-472	€123,60 Mengenrabatte	13 In Stock
-	300.0 x 300.0	0.19	Uncoated, Protective Film on Both Sides	Polymer Film XP40HT- 18	#29-461	€203,94 Mengenrabatte	9 In Stock
-	300.0 x 300.0	0.40	Uncoated, Protective Film on Both Sides	Polymer Film XP40HT- 40	#29-473	€203,94 Mengenrabatte	9 In Stock
-	500.0 x 600.0	0.19	Uncoated, Protective Film on Both Sides	Polymer Film XP40HT- 18	#29-462	€300,76 Mengenrabatte	13 In Stock
-	600.0 x 500.0	0.40	Uncoated, Protective Film on Both Sides	Polymer Film XP40HT- 40	#29-475	€300,76 Mengenrabatte	3 In Stock
-	600.0 x 1000.0	0.19	Uncoated, Protective Film on Both Sides	Polymer Film XP40HT- 18	#29-464	€432,60 Mengenrabatte	2 In Stock
-	600.0 x 1000.0	0.22	Pressure Sensitive Adhesive (PSA) one-sided, Protective Film on Both Sides	Polymer Film XP40HT- 18	#29-463	€432,60 Mengenrabatte	1 In Stock
-	600.0 x 1000.0	0.40	Uncoated, Protective Film on Both Sides	Polymer Film XP40HT- 40	#29-474	€432,60 Mengenrabatte	9 In Stock



Copyright 2023 | Edmund Optics, Ltd Unit 1, Opus Avenue, Nether Poppleton, York, YO26 6BL, UK

Telefonnr.: 1-800-363-1992 :

www.edmundoptics.com